


# Coil Assembly LZ-050-HT-XXX


Dimensions mm [in]

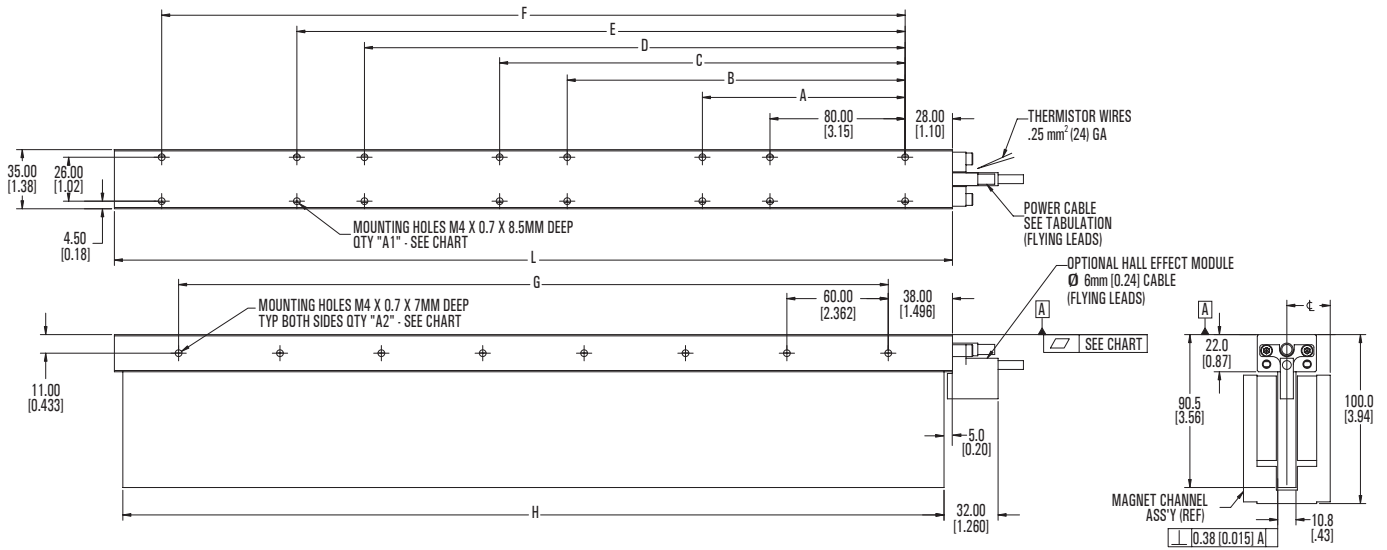

| Coil    |                |                |                |                |                 |                 |                 |                 |               |        |        |             |
|---------|----------------|----------------|----------------|----------------|-----------------|-----------------|-----------------|-----------------|---------------|--------|--------|-------------|
| Size    | L              | A              | B              | C              | D               | E               | F               | G               | H             | A1 QTY | A2 QTY | Flatness A  |
| 050-120 | 136.00 (5.35)  | ---            | ---            | ---            | ---             | ---             | ---             | 60.00 (2.362)   | 126.0 (4.96)  | 4      | 3      | 0.25 (.010) |
| 050-240 | 256.00 (10.08) | 120.00 (4.724) | 200.00 (7.874) | ---            | ---             | ---             | ---             | 180.00 (7.087)  | 246.0 (9.69)  | 8      | 5      | 0.25 (.010) |
| 050-360 | 376.00 (14.80) | 120.00 (4.724) | 200.00 (7.874) | 240.00 (9.449) | 320.00 (12.598) | ---             | ---             | 300.00 (11.811) | 366.0 (14.41) | 12     | 7      | 0.38 (.015) |
| 050-480 | 496.00 (19.53) | 120.00 (4.724) | 200.00 (7.874) | 240.00 (9.449) | 320.00 (12.598) | 360.00 (14.173) | 440.00 (17.323) | 420.00 (16.535) | 486.0 (19.13) | 16     | 9      | 0.64 (.025) |

| Magnet Channel |               |   |          |             |             |
|----------------|---------------|---|----------|-------------|-------------|
| Size           | L             | X | Hole Qty | —           | ▨           |
| -120           | 119.0 (4.69)  | 1 | 2        | 0.13 (.005) | 0.13 (.005) |
| -180           | 179.0 (7.05)  | 2 | 3        | 0.13 (.005) | 0.13 (.005) |
| -240           | 239.0 (9.41)  | 3 | 4        | 0.13 (.005) | 0.13 (.005) |
| -480           | 479.0 (18.86) | 7 | 8        | 0.26 (.010) | 0.26 (.010) |
| -600           | 599.0 (23.58) | 9 | 10       | 0.26 (.010) | 0.26 (.010) |

# Magnet Channel LZM-050-HT-XXX

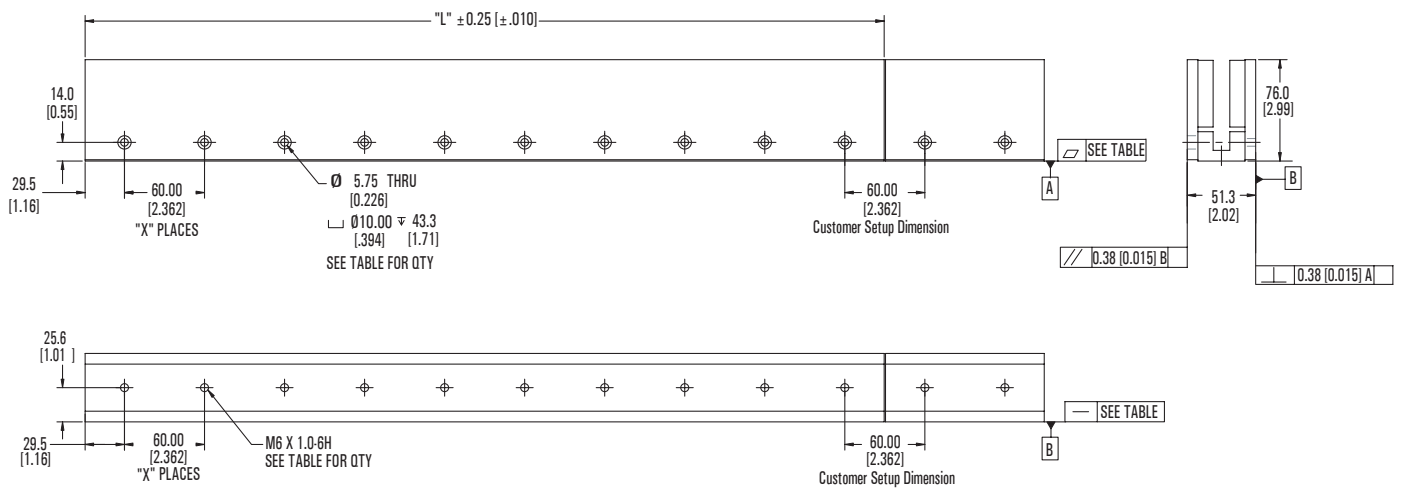

Tolerances

|           |               |
|-----------|---------------|
| Metric    | English       |
| .x ± .25  | [.xx] ± .01   |
| .xx ± .13 | [.xxx] ± .005 |